



OS315-400

Installation instruction


1 OS315-400

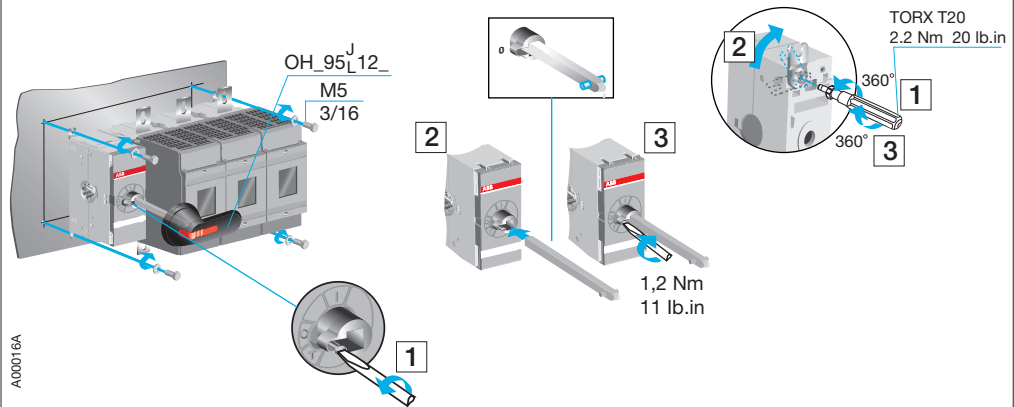

2 OS315-400_01-04

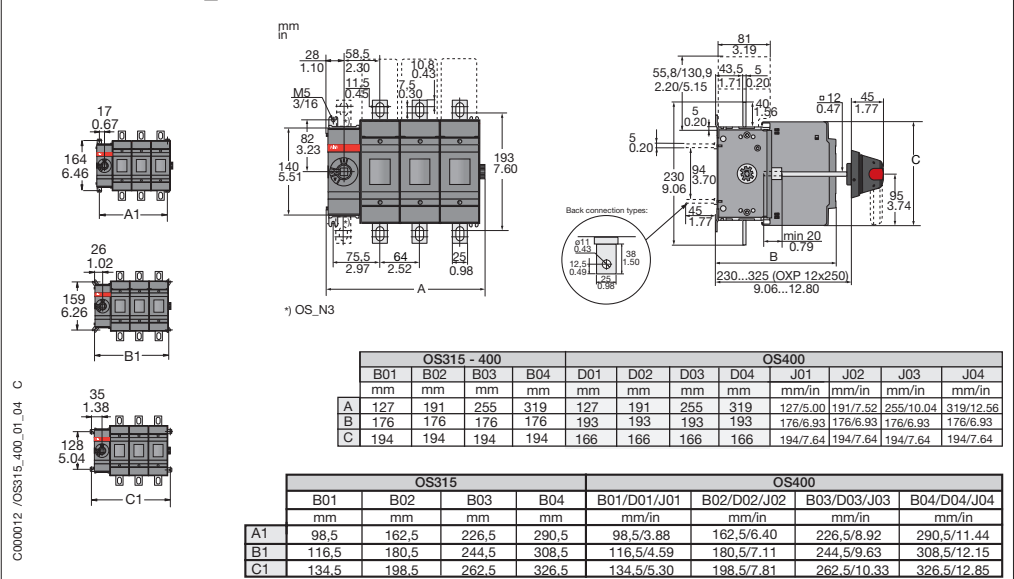

3 OS315-400_11-22

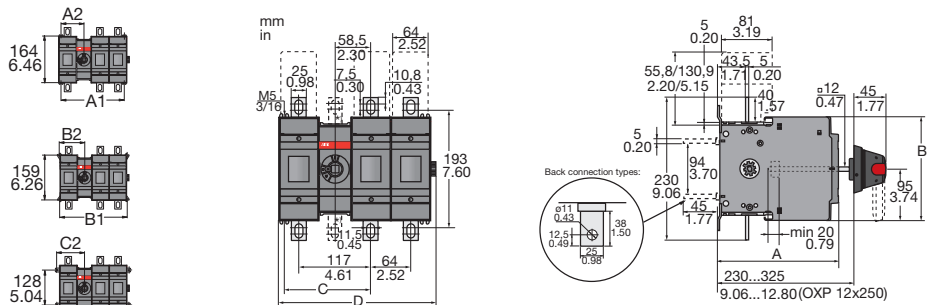

*OS_N3

	OS315-400					OS400											
	B11	B12	B13	B21	B22	D11	D12	D13	D21	D22	J11	J12	J13	J21	J22		
	mm	mm	mm	mm	mm	mm	mm	mm	mm	mm	mm/in	mm/in	mm/in	mm/in	mm/in		
A	176	176	176	176	176	193	193	193	193	193	176/6.93	176/6.93	176/6.93	176/6.93	176/6.93		
B	194	194	194	194	194	166	166	166	166	166	194/7.64	194/7.64	194/7.64	194/7.64	194/7.64		
C	140	140	140	204	204	140	140	140	204	204	140/5.51	140/5.51	140/5.51	204/8.03	204/8.03		
D	190	254	318	254	318	190	254	318	254	318	190/7.48	254/10.00	318/12.52	254/10.00	318/12.52		

	OS315					OS400				
	B11	B12	B21	B22	B13	B11/D11/J11	B12/D12/J12	B21/D21/J21	B22/D22/J22	B13/D13/J13
	mm	mm	mm	mm	mm	mm/in	mm/in	mm/in	mm/in	mm/in
A1	163	227	227	291	291	163/6.42	227/8.94	227/8.94	291/11.46	291/11.46
A2	81.5	81.5	145.5	145.5	81.5	81.5/3.21	81.5/3.21	145.5/5.73	145.5/5.73	81.5/3.21
B1	181	245	245	309	309	181/7.13	245/9.65	245/9.65	309/12.17	309/12.17
B2	90.5	90.5	154.5	154.5	90.5	90.5/3.56	90.5/3.56	154.5/6.08	154.5/6.08	90.5/3.56
C1	199	263	263	327	327	199/7.83	263/10.35	263/10.35	327/12.87	327/12.87
C2	99.5	99.5	163.5	163.5	99.5	99.5/3.92	99.5/3.92	163.5/6.44	163.5/6.44	99.5/3.92

C000011 OS315-400_11_22 C


4 OZX_

OS315, OS400


OZXB2L
OZXB3
OZXB4
OZXB7
OZXB7L
OZXB8
OZXB9

OS400J


OZXA-400
OZXA-406

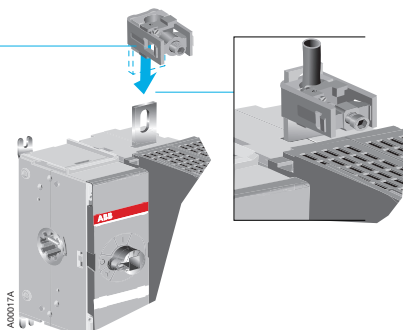

5 Fuse links

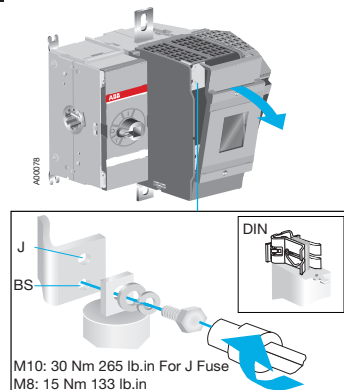


6 Label

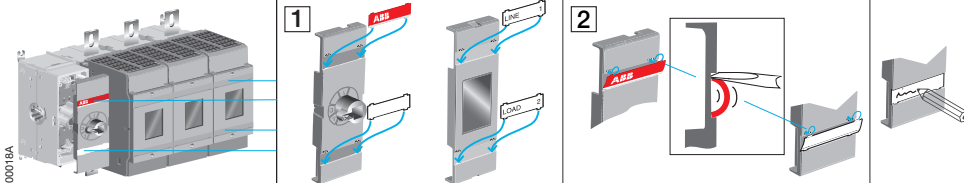


7

OSP_

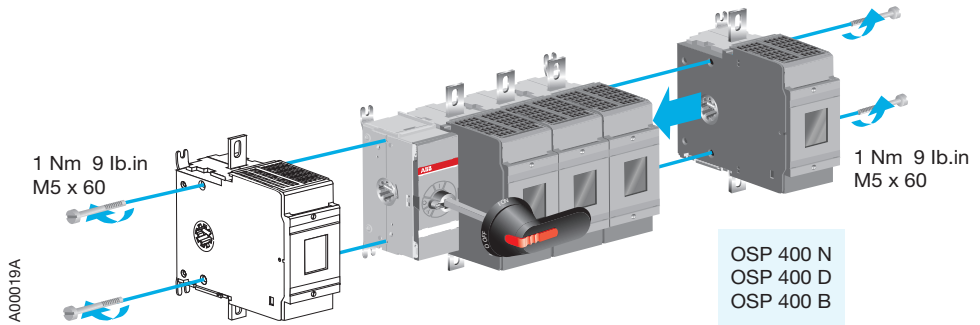



8

OS_N3, OXN400

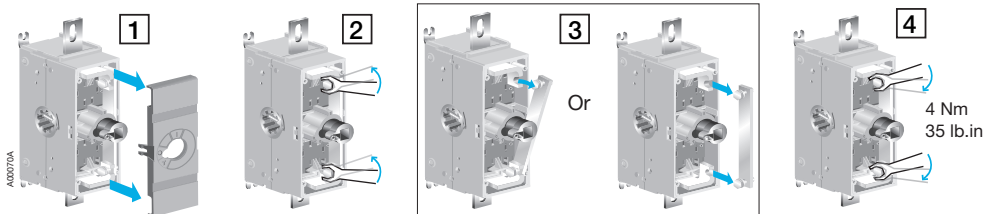

9

Clearances per UL98

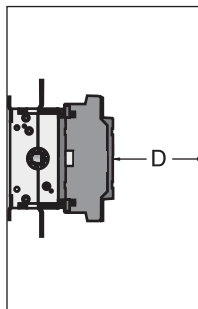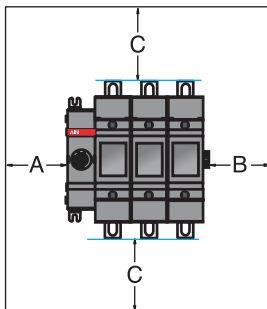

A	B	D
0	13 mm 0.5 in	13 mm 0.5 in

C Cable size AWG/MCM	
4-3	250
100 mm 4 in	200 mm 8 in
2	300
100 mm 4 in	250 mm 10 in
1	400
100 mm 4 in	330 mm 13 in
1/0	500
125 mm 5 in	356 mm 14 in
2/0	600
150 mm 6 in	381 mm 15 in
3/0 - 4/0	
175 mm 7 in	

Minimum enclosure size or equivalent volume

Switch	Height	Width	Depth
3-pole	610	356	254
4-pole	610	508	254


A00104A




11 OFS_






OS315-400...+OFS_

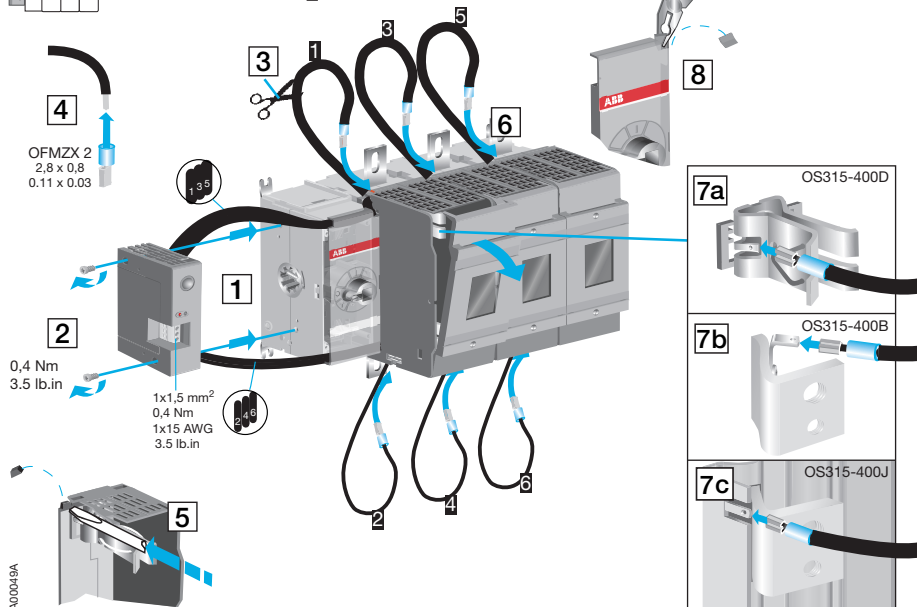



12 OSS_

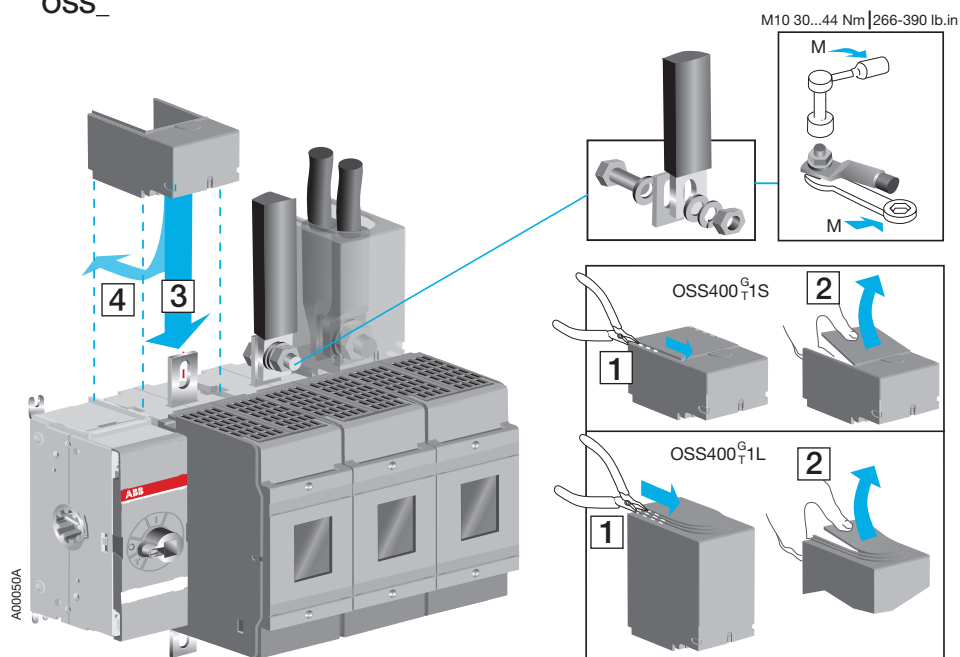


15 OSV_

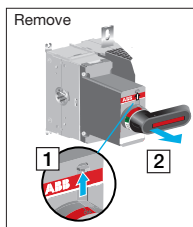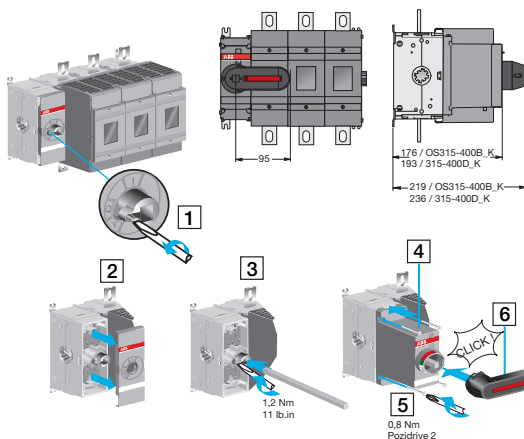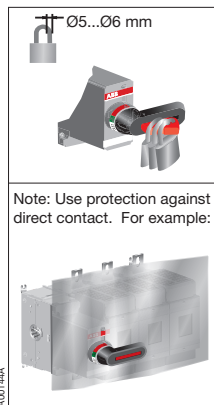



16 OA_

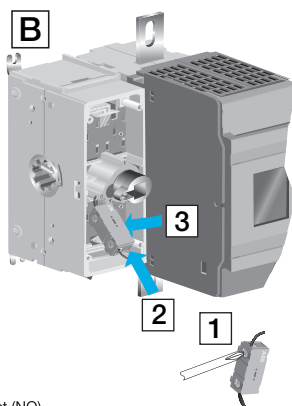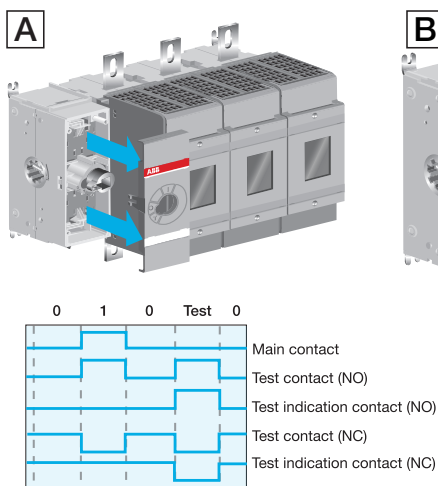

NO: OA1G10
NC: OA3G01
Test contact

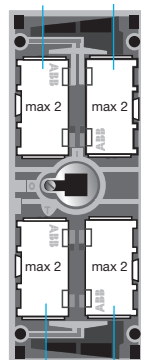

Test indication contact

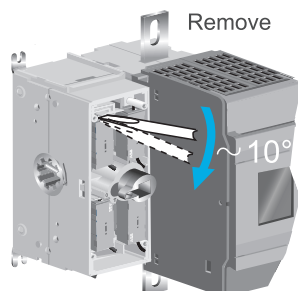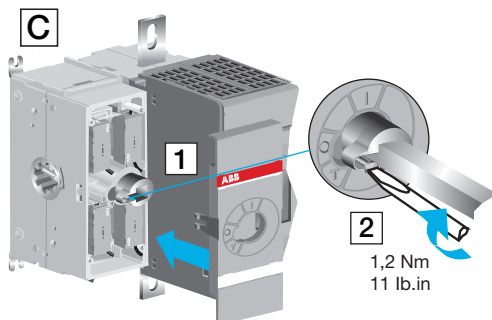

A00080A



BG	Внимание! Опасно напряжение! Да се монтира само от лице с електротехническа квалификация.
FR	Avertissement! Tension électrique dangereuse! Installation uniquement par des personnes qualifiées en électrotechnique.
MT	Twissija! Vultaġġ perikoluż! Għandu jiġi installat biss minn persuna b'kompetenza elettroteknika.
HR	Upozorenje! Opasan napon! Postavljati smije samo elektrotehnički stručnjak.
DE	Warnung! Gefährliche Spannung! Installation nur durch elektrotechnische Fachkraft.
PL	Ostrzeżenie! Niebezpieczne napięcie! Instalacji może dokonać wyłącznie osoba z fachową wiedzą w dziedzinie elektrotechniki.
CZ	Varování! Nebezpečné napětí! Montáž smí provádět výhradně elektrotechnik!
EL	Προειδοποίηση! Υψηλή τάση! Η εγκατάσταση πρέπει να γίνεται μόνο από εξειδικευμένους ηλεκτροτεχνικούς.
PT	Aviso! Tensão perigosa! A instalação só deve ser realizada por um electricista especializado.
DA	Advarsel! Farlig elektrisk spænding! Installation må kun foretages af personer med elektroteknisk ekspertise.
HU	Figyelmeztetés! Veszélyes feszültség! Csak elektrotechnikai tapasztalattal rendelkező szakember helyezheti üzembe.
RO	Avertizare! Tensiune periculoasă! Instalarea trebuie efectuată numai de către o persoană cu experiență în electrotehnică.
NL	Waarschuwing! Gevaarlijke spanning! Mag alleen geïnstalleerd worden door een deskundige elektrotechnicus.
IE	Rabhadh! Voltas guaiseach! Ba chóir do dhuine ag a bhfuil saineolas leictreicniúil, agus an té sin amháin, é seo a shuiteáil.
SK	Varovanie! Nebezpečné napätie! Montáž môže vykonávať iba skúsený elektrotechnik.
EN	Warning! Hazardous voltage! Installation by person with electrotechnical expertise only.
IT	Avvertenza! Tensione pericolosa! Fare installare solo da un elettricista qualificato.
SL	Opozorilo! Nevarna napetost! Vgradnjo lahko opravi le oseba z elektrotehničnim strokovnim znanjem.
ET	Hoiatus! Ohtlik pinge. Paigaldada võib ainult elektrotehnika-alane ekspert.
LV	Uzmanību! Bīstami - elektrība! Montāžas darbus drīkst veikt tikai personas, kurām ir atbilstošas elektrotehniskās zināšanas.
ES	¡Advertencia! ¡Tensión peligrosa! La instalación deberá ser realizada únicamente por electricistas especializados.
FI	Varoitus! Vaarallinen jännite! Asennuksen voi tehdä vain sähköalan ammattihenkilö.
LT	Dėmesio! Pavojinga įtampa! Dirbti leidžiama tik elektrotechniko patirties turintiems asmenims.
SE	Varning! Farlig spänning! Installation får endast utföras av en elektriker.
CN	警告！电压危险！只能由专业电工进行安装。
RU	Осторожно! Опасное напряжение! Монтаж должен выполняться только специалистом-электриком.

For more information please contact:

ABB Oy, Protection and Connection
P.O. Box 622, FI-65101 Vaasa, Finland
new.abb.com/low-voltage

Power and productivity
for a better world™

