



OHM45L5



OHM65L5



OHM65L6



OHM125L12



OHM175L12



OHM275L12



OHB2_JEH

New stainless steel handle range for front operated switch-disconnectors and switch fuses

The new acid-proof stainless steel pistol type handles are available in lengths from 45 to 275 mm for shaft diameters 5, 6 and 12 mm. They are padlockable with three padlocks in the OFF-position and the door is interlockable in the ON-position.

Screw fixing from the back side of the handle with included washers which ensure the earthing of the handle also on painted surfaces. No screws on the front.



Pistol type handles for switch-disconnectors and switch fuses

Protection class IP66 (NEMA 4, 4X, 12)

Colour	Handle length [mm]	Type	Order number	Delivery batch [pcs]	Weight/unit [kg]
For shaft diameter 5 mm					
Pistol handle. I-O/ON-OFF					
Grey	45	OHM45L5	1SCA022739R0850	1	0.65
Grey	65	OHM65L5	1SCA022739R0930	1	0.73
For shaft diameter 6 mm					
Pistol handle. I-O/ON-OFF					
Grey	65	OHM65L6	1SCA022739R1070	1	0.73
For shaft diameter 12 mm					
Pistol handle. I-O/ON-OFF					
Grey	125	OHM125L12	1SCA022739R1150	1	0.76
Grey	175	OHM175L12	1SCA022739R1230	1	0.83
Grey	275	OHM275L12	1SCA022832R4840	1	0.96

Handles with metal hasp for door mounted switch-disconnectors

Selector type handle, I-O/ON-OFF. Protection class IP 65/NEMA 1, 3R, 12. Snap-on mounting, door drilling 22.5 mm. Padlockable with max. 3 padlocks.

Colour	Suitable for switches	Type	Order number	Delivery batch [pcs]	Weight/unit [kg]
Black	OT16...32ET	OHB2PJEH	1SCA022832R9130	1	0.08

Handles with metal hasp for base and DIN-rail mounted switch-disconnectors


Selector type handle, I-O/ON-OFF. Protection class IP65/NEMA 1, 3R, 12, door drilling 22.5 mm, padlockable with max. 3 padlocks. Door interlock in the ON-position, defeatable.

Colour	Suitable for switches	Type	Order number	Delivery batch [pcs]	Weight/unit [kg]
Black	OT16...125E	OHB2AJEH	1SCA022841R5560	1	0.08

Stainless steel handles

Dimension drawings


OHM_

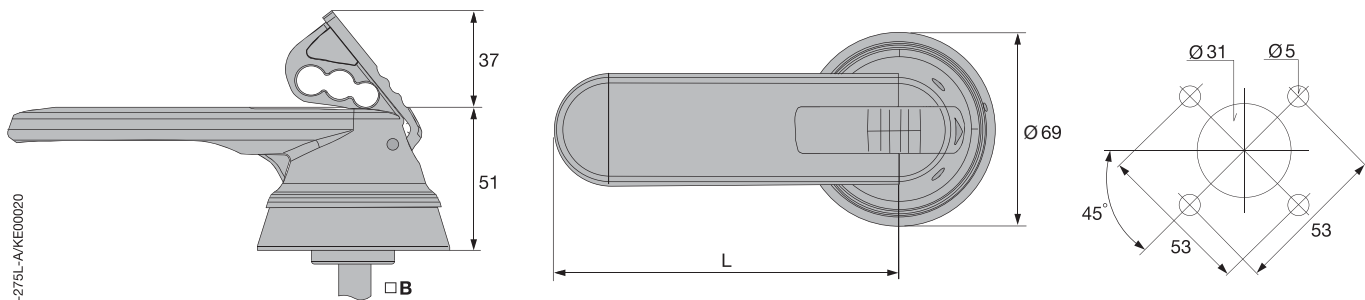

M00133/13OHM45-275L-A/KE00020


Handle type	OHM45L5	OHM65L5	OHM65L6	OHM125L12	OHM175L12	OHM275L12
L	45	65	65	125	175	275
□B	5	5	6	12	12	12

OHB2PJEH

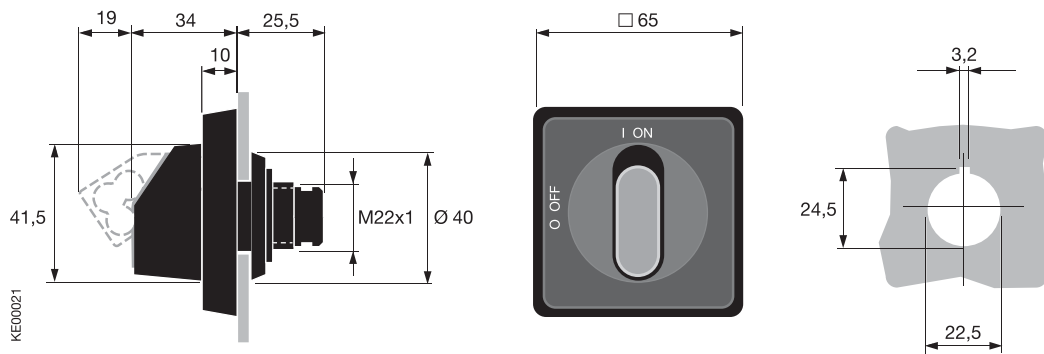

KE00021

OHB2AJEH

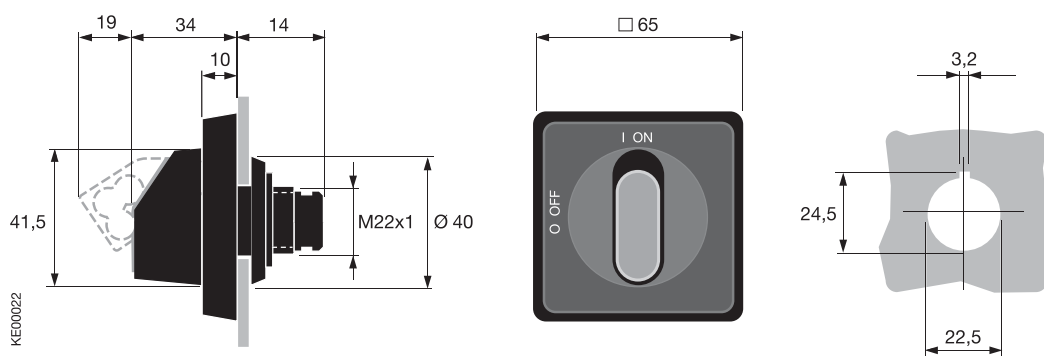

KE00022



ABB Oy
 Low Voltage Products
 P.O. Box 622
 FI-65101 VAASA, Finland
 Telephone +358 10 22 11
 Telefax +358 10 22 45708
www.abb.com

The technical data and dimensions are valid at the time of printing. We reserve the right to subsequent alterations.