


Label holder

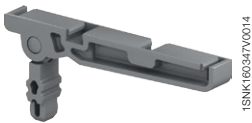

LH
spacing

LH-J label holder

Description

Easily identify your block with three standard 5.2 mm 0.205 in spacing SNK markers. It fits in the jumper channel of the SNK Terminal blocks.

Ordering details

Description	Color	Type	Order code	Pkg qty	Weight (1 pce) g
Rotating label holder with three SNK markers housings - 4.8 mm 0.189 in spacing	Dark grey	LH-J	1SNK900606R0000	100	0.73

Main technical data

Material specifications	Insulating material	Polyamide			
	Flammability	V0			
	NF F 16 101	I2F2			
Ambient temperature min/max	Service IEC 60068-2-1	-55 ... +110 °C	-67 ... +230 °F		
	Storage	-55 ... +110 °C	-67 ... +230 °F		
	Installing	-5 ... +40 °C	+23 ... +104 °F		

All the main technical data provided are *manufacturer* values

		RoHS																	
		RoHS																	

Accessories

Description		Color	Type	Order code	Pkg qty	Weight (1 pce) g
Blank card	compatible with HTP500	White	MC512	1SNK140000R0000	22	9.00
	compatible with AMS500	White	MC512PA	1SNK149999R0000	20	10.00
Universal wire markers holder	5.2 mm 0.205 in spacing	Grey	UMH	1SNK900611R0000	10	0.20
Blank marker	compatible with MG3	White	MG-CPM 13 41790	1SNB041790R0512	1960	0.23

All the technical data for UL/CSA standard and dimensions in inches are in italic.
Technical data valid for copper conductors only.