


Accessories for Enclosures

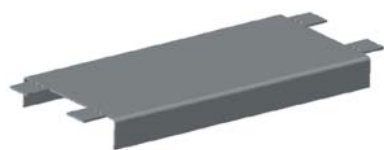

C20-BP, C40-BP, C60-BP
Sheet steel foundation base plate for CDC/CDCM.



BERG 250
Rock hold for cable distribution cabinets type CDC when installed in rocky ground.



 
FDM-K
Mounting kit developed for mounting fibre duct module FDM (Ericsson Ribbonet) on Kabeldon IP-system.



FV
Wall bracket for enclosures CDC/CDCM.



FDM
Fibre duct module is used for jointing fibre optic ducts. The duct in the service cable is jointed to a multi-duct cable.



C20-DB, C40-DB, C60-DB
Damp barrier, fits all CDC enclosures.



VF 100
Wall bracket for enclosures CDC and SDC. Keeps the CDC cabinet 100 mm away from the wall of the building. For SDC, the distance from the wall is 8 mm.



FVD
Wall spacer, used together with FV.



KSPS 6
Marking pole.



C60-XA
Extra anchor bar which can be installed under the cover plate in CDC 60. It is used when replacing enclosure where the cable must be jointed.

Designation	ID No.	Suitable for	Dimensions			Weight
			Height	Width	Depth	
			mm			kg/pcs
C 20-BP	2CGX0 53310725	CDC/CDCM 20	27	344	130	0.8
C 40-BP	2CGX0 53310726	CDC/CDCM 40	27	594	130	1.5
C 60-BP	2CGX0 53310727	CDC 60	27	844	130	2.2
BERG 250	2CGX0 63300649	CDC/CDCM	370	130	30	1.9
FDM-K	2CGX0 53310704	CDC/SDC	–	–	–	0.1
FV	2CGX0 63190225	CDC/CDCM	50	70	135	1.9
FDM	2CMA1 31600R1000	CDC/SDC	506	135	93	1.0
C20-DB	2CGX0 53310696	CDC	50	350	215	0.2
C40-DB	2CGX0 53310697	CDC	50	600	215	0.3
C60-DB	2CGX0 53310698	CDC	50	850	215	0.4
VF 100	2CGX0 53310678	CDC/CDCM/SDC/SDCM	40	228	35	0.2
FVD	2CGX0 63190241	FV	–	Ø 47	85	0.7
KSPS 6	2CGX0 63190145	CDC/CDCM/SDC/SDCM	1500	30	30	3.8
C60-XA	2CGX0 53310667	CDC 60	42	935	50	1.7